


Outline Dimensions

HW1223

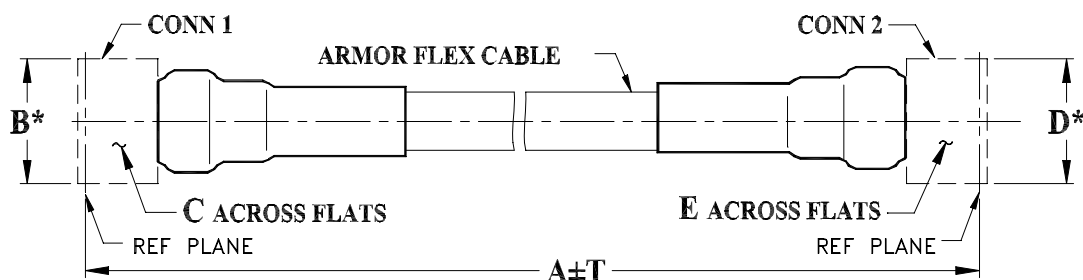

* OVERALL CONNECTOR OR CABLE & BOOT DIMENSION
(CONNECTOR SHAPE MAY VARY)

HW1223 SERIES
SMA MALE (CONN-1)
N MALE (CONN-2)

CASE STYLE #	A		B	C	D	E	T		WEIGHT GRAMS
	FEET	METERS					FEET	METERS	
HW1223-1	1	.30	.70 (17.78)	.312 (7.92)	.88 (22.35)	.750 (19.05)	.06	.02	148
HW1223-2	2	.61					.06	.02	225
HW1223-3	3	.91					.09	.03	301
HW1223-3.28	3.28	1.00					.10	.03	322
HW1223-4	4	1.22					.12	.04	377
HW1223-5	5	1.52					.15	.05	453
HW1223-6	6	1.83					.18	.05	529
HW1223-7	7	2.13					.21	.06	606
HW1223-8	8	2.44					.24	.07	682
HW1223-9	9	2.74					.27	.08	758
HW1223-10	10	3.05					.30	.09	834
HW1223-11	11	3.35					.33	.10	910
HW1223-12	12	3.66					.36	.11	987
HW1223-13	13	3.96					.39	.12	1063
HW1223-14	14	4.27					.42	.13	1139
HW1223-15	15	4.57					.45	.14	1215
HW1223-16	16	4.88					.48	.15	1291
HW1223-17	17	5.18					.51	.16	1368
HW1223-18	18	5.49					.54	.16	1444
HW1223-19	19	5.79					.57	.17	1520
HW1223-20	20	6.10	.60	.18	1596				

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. $\pm .03$; 3Pl. $\pm .015$

Note:

1. Flexible Coaxial Cable.

Mini-Circuits[®]

INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified