


Case Style





QM

Outline Dimensions

QM2280

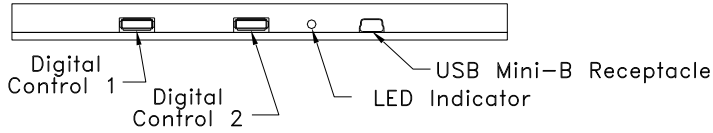

 Bracket Option

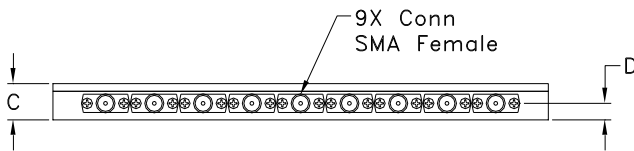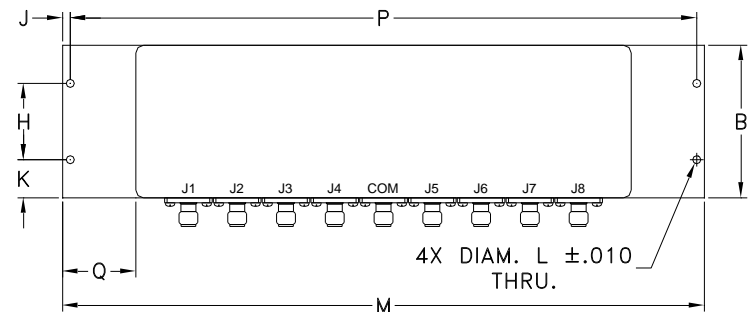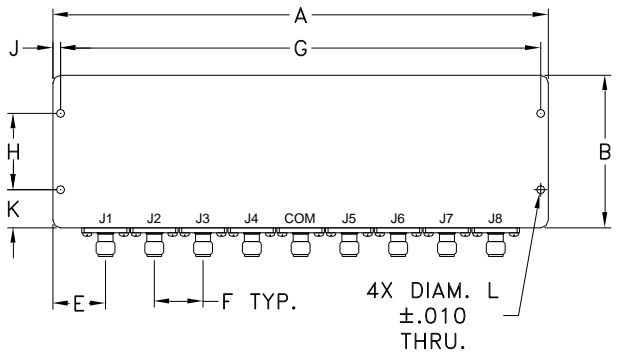

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	N	P
QM2280	6.50 (165.1)	2.00 (50.8)	.475 (12.07)	.217 (5.51)	.69 (17.53)	.640 (16.26)	6.300 (160.02)	1.000 (25.40)	.10 (2.54)	.50 (12.70)	.106 (2.69)	8.42 (213.87)	.125 (3.18)	8.220 (208.79)

CASE#	Q	WT. GRAMS
QM2280	.96 (24.38)	400

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .015

Notes:

1. Case material: Nickel Plated Aluminum.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified