


## Outline Dimensions

QM2605

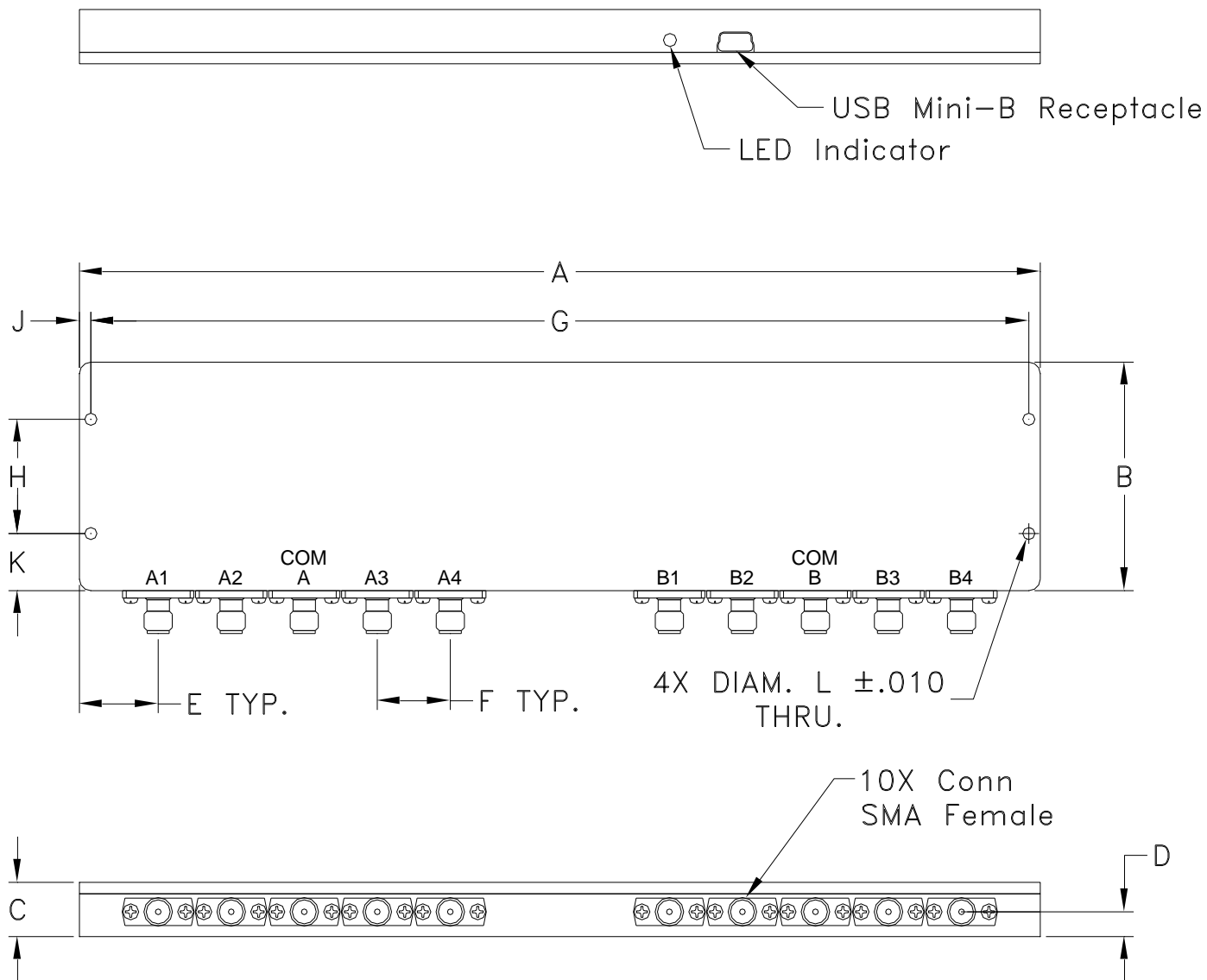

| CASE#  | A               | B              | C               | D              | E              | F               | G                 | H                | J             | K              | L              | WT. GRAMS |
|--------|-----------------|----------------|-----------------|----------------|----------------|-----------------|-------------------|------------------|---------------|----------------|----------------|-----------|
| QM2605 | 8.42<br>(213.9) | 2.00<br>(50.8) | .475<br>(12.06) | .217<br>(5.51) | .69<br>(17.53) | .640<br>(16.26) | 8.220<br>(208.79) | 1.000<br>(25.40) | .10<br>(2.54) | .50<br>(12.70) | .106<br>(2.69) | 440       |

Dimensions are in inches (mm). Tolerances: 2PL. +/- .03; 3PL. +/- .015

### Notes:

1. Case material: Nickel Plated Aluminum.



INTERNET <http://www.minicircuits.com>

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified