


### Outline Dimensions

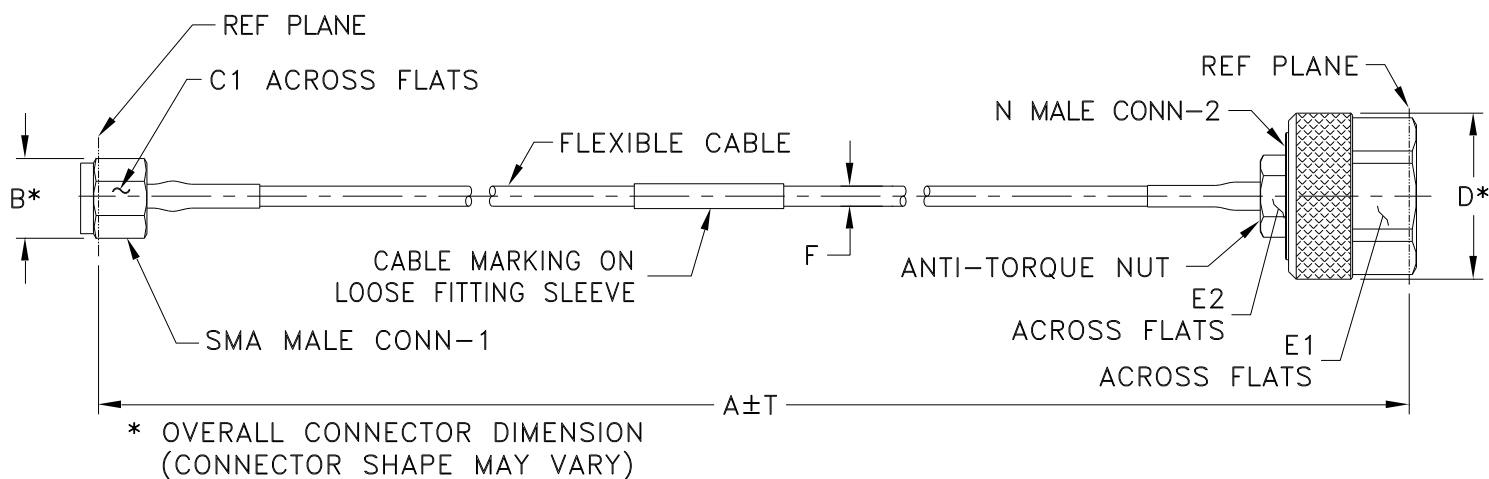

SE2635 SERIES  
 SMA MALE (CONN-1)  
 N MALE (CONN-2)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F FL086-ASMNM+	T		WEIGHT GRAMS
	INCH	MM								INCH	MM	
SE2635-6	6	152.4	.36 (9.14)	.313 (7.95)	-	.88 (22.0)	.750 (19.0)	.375 (9.5)	.106±.004 (2.64±0.1)	0.05	1.27	40.01
SE2635-12	12	304.8								0.10	2.54	42.92
SE2635-24	24	609.6								0.15	3.81	48.74

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2Pl. ± .03; 3Pl. ± .015

Note:

- 086 Flexible Coaxial Cable.
- "A" Represents Length of Cable.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS