


# Case Style

# SE

## Outline Dimensions

## SE3045

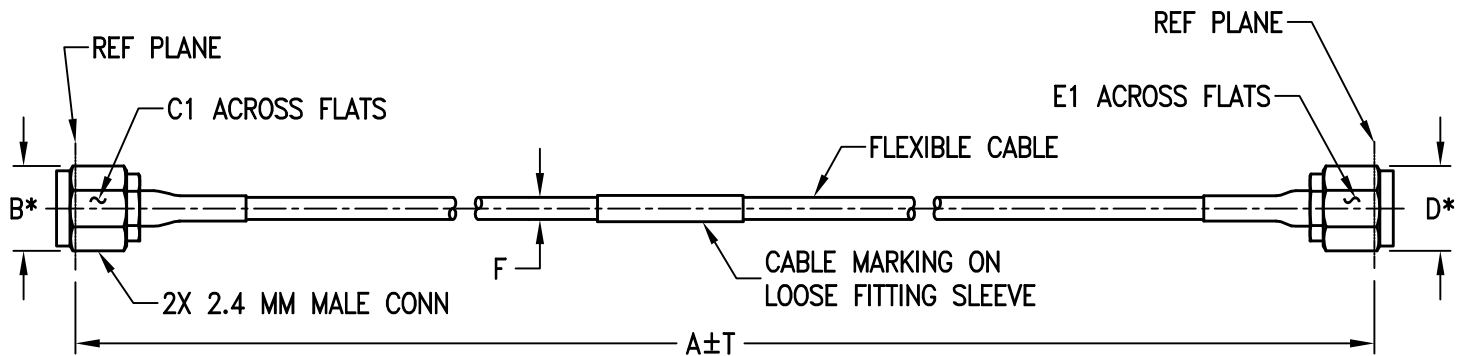

\* OVERALL CONNECTOR DIMENSION  
(CONNECTOR SHAPE MAY VARY)

### SE3045 SERIES 2.4 MM MALE (CONN)

CASE STYLE #	A		B	C1	C2	D	E1	E2	F	T		WT. (GRAMS)
	INCH	MM							FL86-AVM+	INCH	MM	
SE3045-12	12.00	304.80	0.36 [9.14]	.315 [8.00]	-	.36 [9.14]	.315 [8.00]	-	.106±.004 (2.64±0.1)	.10	2.54	12.20

Unless otherwise specified dimensions are in inches (mm).

Tolerances: 2 Pl. ±.03; 3 Pl. ±.015

Note:

- 086 Flexible Coaxial Cable.
- "A" Represents Length of Cable.

**Mini-Circuits®**  
ISO 9001 ISO 14001 CERTIFIED

ALL NEW  
minicircuits.com

P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS