


## Outline Dimensions

UU537

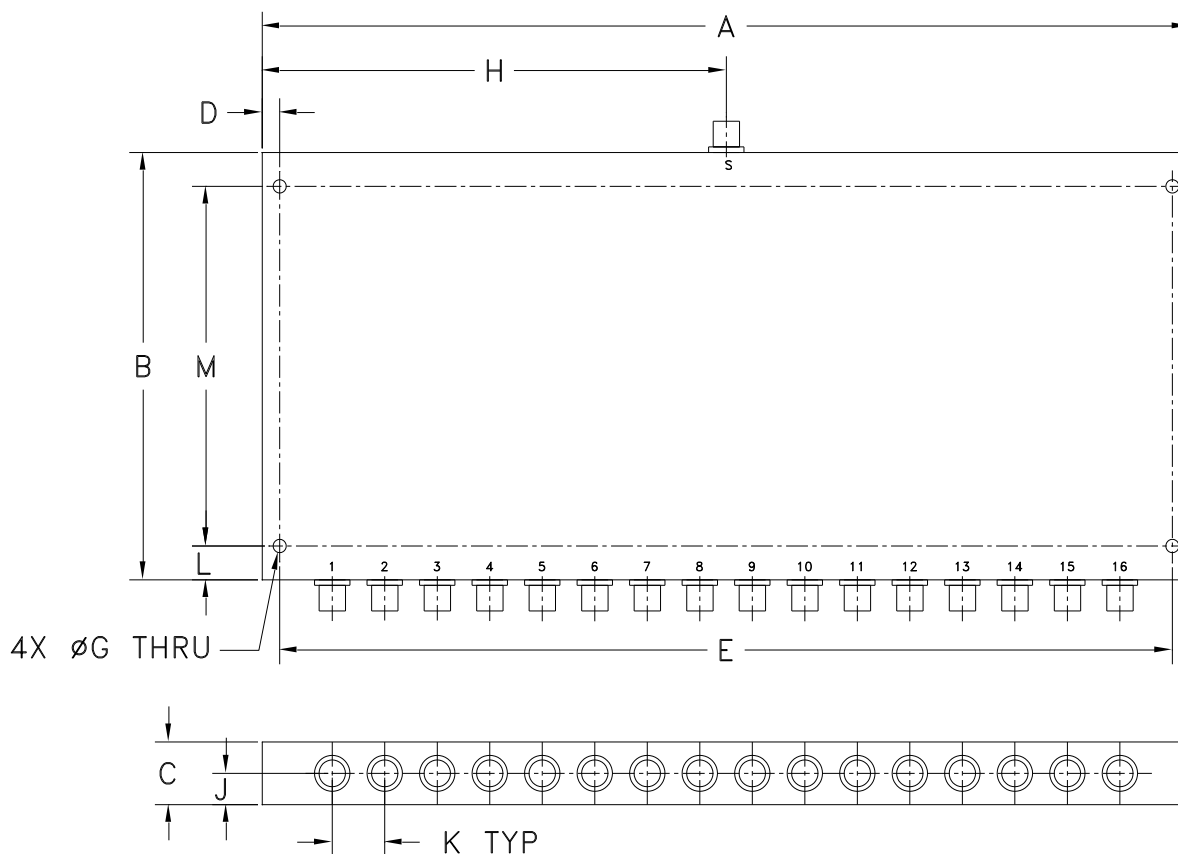

CASE#	A	B	C	D	E	F	G	H	J	K	L	M	WT. GRAMS
UU537	13.25 (336.55)	6.00 (152.40)	.88 (22.35)	.250 (6.35)	12.75 (323.85)	-- --	.187 (4.75)	6.63 (168.40)	.44 (11.18)	.75 (19.05)	.48 (12.19)	5.05 (128.27)	2080

Dimensions are in inches (mm). Tolerances: 2 Pl.  $\pm .03$ ; 3 Pl.  $\pm .015$

### Notes:

1. Case material: Aluminum alloy.
2. Case finish:  
For RoHS Case Styles: Clear chemical conversion coating, non-chrome or trivalent chrome based.
3. Refer to the individual model data sheet for the type of connectors available.



P.O. Box 350166, Brooklyn, New York 11235-0003 (718) 934-4500 Fax (718) 332-4661 For detailed performance specs & shopping online see Mini-Circuits web site



The Design Engineers Search Engine Provides ACTUAL Data Instantly From MINI-CIRCUITS At: [www.minicircuits.com](http://www.minicircuits.com)

RF/IF MICROWAVE COMPONENTS