


Case Style

V V

VV105

Outline Dimensions

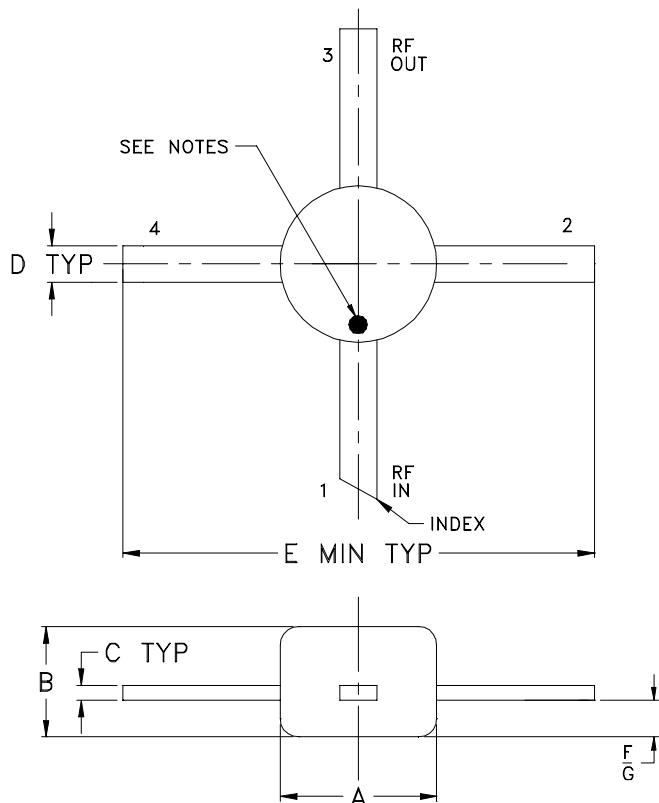

CASE#	A	B	C	D	E	F	G	WT.GRAMS
VV105	.085 (2.16)	.060 (1.52)	.008 (0.20)	.020 (0.51)	.250 (6.35)	.012 (0.30)	.025 (0.64)	.015

Dimensions are in inches (mm). Tolerances: 2 Pl. $\pm .03$; 3 Pl. $\pm .015$

Notes:

1. Case material: Plastic.
2. Termination finish:
 - For RoHS Case Styles: Tin-Silver alloy plate over Nickel barrier.
 - For RoHS-5 Case Styles: Tin-Lead plate.
3. RF input termination (1) identified by one or both of the following at factory option:
 - (a) diagonally cut termination, which be 45° (ref) in either direction;
 - (b) orientation mark on the case. Model dash number is identified by color dot or alphanumeric code on case. See specification data sheet.
4. Special Tolerances: Termination width $\pm .005$ inch, termination thickness $\pm .003$ inch.

 **Mini-Circuits**[®]

Distribution Centers NORTH AMERICA 800-654-7949 • 417-335-5935 • Fax 417-335-5945 • EUROPE 44-1252-832600 • Fax 44-1252-837010

Mini-Circuits ISO 9001 & ISO 14001 Certified

INTERNET <http://www.minicircuits.com>